


# Product data sheet

Specifications

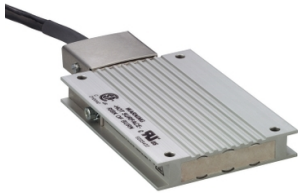

braking resistor - 72 ohm - 200 W -  
cable 0.75 m - IP65

VW3A7606R07

Product availability: Non-Stock - Not normally stocked in  
distribution facility

Price\*: 203.00 USD

## Main

Range Of Product	Lexium Altivar
Range Compatibility	Lexium 05 Altivar 32 Lexium 52 Lexium 28 Lexium 32 Lexium 15 Altivar Machine ATV320 Lexium 32i Easy Lexium 16
Product Compatibility	ATV32HU30N4 ATV32HU40N4 Variable speed drive ATV320 3 kW, 380...500 V, three phase Variable speed drive ATV320 4 kW, 380...500 V, three phase Variable speed drive ATV320 4 kW, 525...600 V, three phase Motion servo drive LXM16D 0.1 kW, 200...230 V, single phase Motion servo drive LXM16D 0.2 kW, 200...230 V, single phase Motion servo drive LXM16D 0.4 kW, 200...230 V, single phase Motion servo drive LXM16D 0.75 kW, 200...230 V, single phase Motion servo drive LXM16D 1 kW, 200...230 V, single phase Motion servo drive LXM16D 1.5 kW, 200...230 V, single phase
Product Or Component Type	Braking resistor
Ohmic Value	72 Ohm

## Complementary

Energy Peak	6000 J 480 V 6600 J 400 V 9600 J 230 V 14600 J 115 V
Average Power Available	50 W 122 °F (50 °C)
Continuous Power	200 W
Protection Type	Thermal protection via the servo drive
Net Weight	2.05 lb(US) (0.93 kg)
Cable Length	2.46 ft (0.75 m)

## Environment

Ip Degree Of Protection	IP65
Ambient Air Temperature For Storage	-13...185 °F (-25...85 °C)
Ambient Air Temperature For Operation	32...122 °F (0...50 °C)

## Ordering and shipping details

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Category	US1PC5118263
Discount Schedule	PC51
Gtin	3389119207232
Returnability	No
Country Of Origin	DE

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.09 in (5.300 cm)
Package 1 Width	4.33 in (11.000 cm)
Package 1 Length	15.55 in (39.500 cm)
Package 1 Weight	32.38 oz (918.000 g)
Unit Type Of Package 2	S04
Number Of Units In Package 2	10
Package 2 Height	11.81 in (30.000 cm)
Package 2 Width	15.75 in (40.000 cm)
Package 2 Length	23.62 in (60.000 cm)
Package 2 Weight	23.00 lb(US) (10.432 kg)

## Contractual warranty

Warranty	18 months
----------	-----------

## Sustainability





**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)


## Well-being performance

 Reach Free Of Svhc	
 Toxic Heavy Metal Free	
 Mercury Free	
 Rohs Exemption Information	Yes
Reach Regulation	<a href="#">REACH Declaration</a>
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
China Rohs Regulation	<a href="#">China RoHS declaration</a>
California Proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>

Dimensions Drawings

Braking Resistor

Dimensions

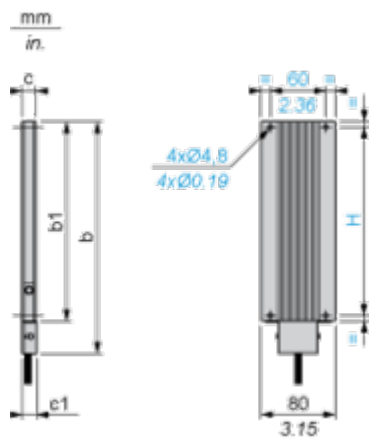

Dimensions in mm

b	b1	c	c1	H
251	216	15	15.5	204

Dimensions in in.

b	b1	c	c1	H
9.88	8.50	0.59	0.61	8.03