


# Product data sheet

Specifications

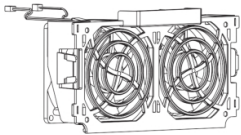

Wear part, enclosure door, fan for variable speed drive, Altivar 340, Altivar Process 600 900, from 7.5 to 22kW

VX5VPS3001

Product availability: Stock - Normally stocked in distribution facility

Price\*: 198.00 USD

## Main

Range Compatibility	Altivar 340 Altivar Process 600/900
Accessory / Separate Part Type	Fan kit
Accessory / Separate Part Category	Cooling accessory
Product Or Component Type	Fan
Net Weight	1.15 lb(US) (0.52 kg)

## Complementary

Kit Composition	Fan Mounting bracket Instruction sheet
Product Compatibility	Variable speed drive ATV630 wall mount 7.5 kW 200...240 V Variable speed drive ATV630 wall mount 11 kW 200...240 V Variable speed drive ATV630 wall mount 15 kW 380...480 V Variable speed drive ATV630 wall mount 18 kW 380...480 V Variable speed drive ATV630 wall mount 22 kW 380...480 V Variable speed drive ATV930 wall mount 7.5 kW 200...240 V Variable speed drive ATV930 wall mount 11 kW 200...240 V Variable speed drive ATV930 wall mount 15 kW 380...480 V Variable speed drive ATV930 wall mount 18 kW 380...480 V Variable speed drive ATV930 wall mount 22 kW 380...480 V

## Ordering and shipping details

Category	US1CP4E22205
Discount Schedule	CP4E
Gtin	3606480715907
Returnability	Yes
Country Of Origin	CN

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.95 in (7.500 cm)
Package 1 Width	6.77 in (17.200 cm)
Package 1 Length	9.17 in (23.300 cm)

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Weight	18.48 oz (524.000 g)
Unit Type Of Package 2	S04
Number Of Units In Package 2	8
Package 2 Height	11.81 in (30.000 cm)
Package 2 Width	15.75 in (40.000 cm)
Package 2 Length	23.62 in (60.000 cm)
Package 2 Weight	11.97 lb(US) (5.430 kg)

## Contractual warranty

Warranty	18 months
----------	-----------

## Sustainability




**Green Premium™** label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

## Well-being performance

 Reach Free Of Svhc	
 Mercury Free	
 Rohs Exemption Information	Yes
Reach Regulation	<a href="#">REACH Declaration</a>
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
China Rohs Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
California Proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>