


Product data sheet

Specifications

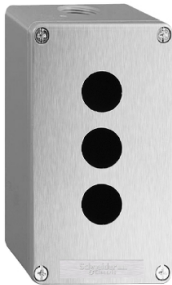

die-cast empty control station,
XAPG, grey, Ø22, 80x130mm front
plate, 3 cut-outs

XAPG2503

⚠ Discontinued on: Jul 1, 2020

⚠ Discontinued

Main

Range Of Product	Harmony XAP
Product Or Component Type	Die-cast empty control station
Device Short Name	XAPG
Product Destination	For Ø 22 mm control and signalling units
Product Front Plate Size	80 x 130 mm
Usable Depth	2.93 in (74.5 mm)
Number Of Cut-Out	3 cut-outs
Colour Of Base Of Enclosure	Grey RAL 7032)
Colour Of Cover	Grey RAL 7032)
Material	Zinc alloy
Product Mounting	Flush mounting
Ip Degree Of Protection	IP65 IEC 60529 IP657 NF C 20-010

Complementary

Number Of Vertical Rows	1
Cable Entry	0.55 in (14 mm) 1 hole with blanking plug for cable gland 0.55 in (14 mm) 1 hole without blanking plug for cable gland
Net Weight	1.80 lb(US) (0.815 kg)
Compatibility Code	XAPG

Environment

Protective Treatment	TH
Ambient Air Temperature For Storage	-40...158 °F (-40...70 °C)
Ambient Air Temperature For Operation	-13...158 °F (-25...70 °C)
Electrical Shock Protection Class	Class I IEC 60536 Class I NF C 20-030

Ordering and shipping details

Category	18406-WORLD SERVICE PARTS(OTHER OP INT)
Discount Schedule	CS2
Gtin	3389110890587

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Returnability	No
---------------	----

Contractual warranty

Warranty	18 months
----------	-----------