


Product data sheet

Specifications

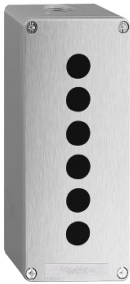

die-cast empty control station,
XAPG, grey, Ø22, 80x175mm front
plate, 6 cut-outs

XAPG3506

⚠ Discontinued on: Oct 20, 2020

⚠ Discontinued

Main

Range Of Product	Harmony XAP
Product Or Component Type	Die-cast empty control station
Device Short Name	XAPG
Product Destination	For Ø 22 mm control and signalling units
Product Front Plate Size	80 x 175 mm
Usable Depth	2.93 in (74.5 mm)
Number Of Cut-Out	6 cut-outs
Colour Of Base Of Enclosure	Grey RAL 7032)
Colour Of Cover	Grey RAL 7032)
Material	Zinc alloy
Product Mounting	Flush mounting
Ip Degree Of Protection	IP65 IEC 60529

Complementary

Number Of Vertical Rows	2
Cable Entry	0.71 in (18 mm) 1 hole with blanking plug for cable gland 0.71 in (18 mm) 1 hole without blanking plug for cable gland
Net Weight	2.49 lb(US) (1.13 kg)
Compatibility Code	XAPG

Environment

Protective Treatment	TH
Ambient Air Temperature For Storage	-40...158 °F (-40...70 °C)
Ambient Air Temperature For Operation	-13...158 °F (-25...70 °C)
Electrical Shock Protection Class	Class I IEC 60536 Class I NF C 20-030

Ordering and shipping details

Category	18406-WORLD SERVICE PARTS(OTHER OP INT)
Discount Schedule	CS2
Gtin	3389110300918
Returnability	No

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	3.54 in (9 cm)
Package 1 Width	4.72 in (12 cm)
Package 1 Length	7.48 in (19 cm)
Package 1 Weight	2.81 lb(US) (1.275 kg)

Contractual warranty

Warranty	18 months
----------	-----------