

Product data sheet

Characteristics

XCCRAS1012

shaft coupling - for encoder - homokinetic with bellows Ø 10 to 12 mm

Product availability : Non-Stock - Not normally stocked in distribution facility

Price* : 120.84 USD



Main

Product or component type	Shaft coupling
Accessory / separate part destination	Rotary encoder with solid shaft
Accessory / separate part category	Coupling accessories
Accessory / separate part type	Homokinetic with bellow
Bore diameter encoder side	0.39 in (10 mm)
Bore diameter machine side	0.47 in (12 mm)

Complementary

Collar material	Aluminium
Bellow material	Stainless steel
Maximum angular misalignment	4°
Maximum axial misalignment	+/- 0.5 mm
Maximum lateral misalignment	+/- 0.3 mm
Torque value	<= 7.08 lbf.in (0.8 N.m)
Product weight	0.03 lb(US) (0.015 kg)

Ordering and shipping details

Category	21581 - ENCODERS, XCC
Discount Schedule	DS2
GTIN	003389110935837
Nbr. of units in pkg.	1
Package weight(Lbs)	1.1000000000000001
Returnability	N
Country of origin	FR

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0701 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold


Reference not containing SVHC above the threshold

California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and
----- Substance 2	Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm.
----- More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------

Dimensions

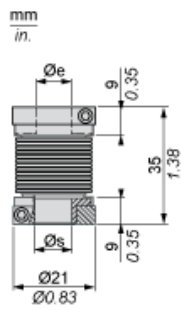

$\varnothing e$	$\varnothing s$
10 mm	12 mm